

NOTES:


- 1. SUBSTRATE MATERIAL: BOROFLOAT®
- 2. COATING (APPLY ACROSS CLEAR APERTURE)

S1: R(AVG) >89% @ 250 - 450nm  
 R(AVG) >85% @ 250 - 700nm

S2: NONE

 3. FINE GRIND SURFACE

4. RoHS COMPLIANT

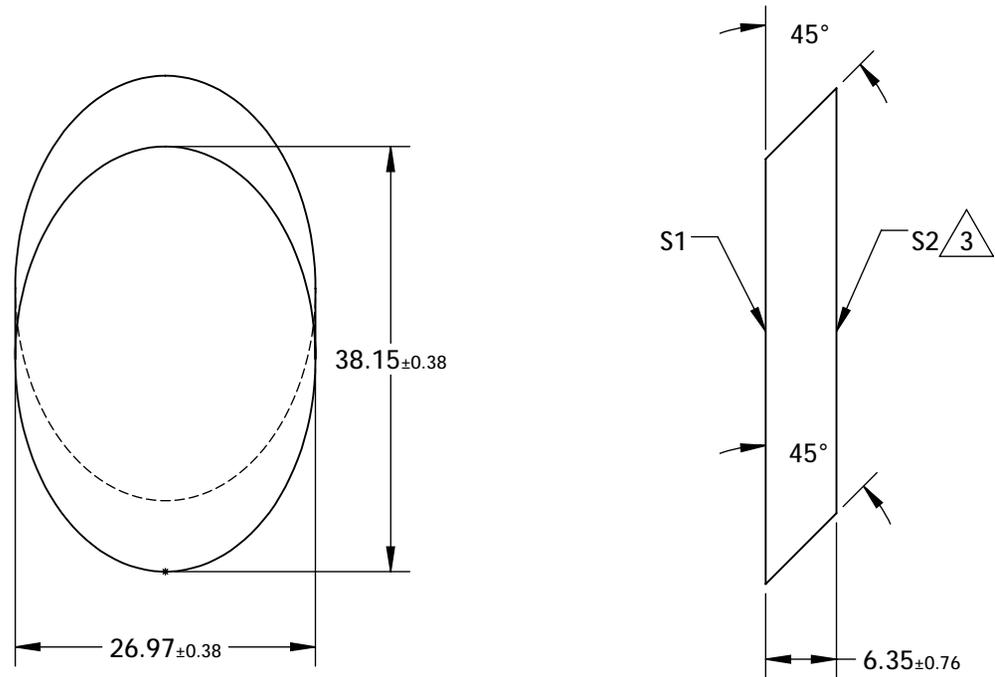


**FOR INFORMATION ONLY:  
 DO NOT MANUFACTURE  
 PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
 DIMENSIONS ARE FOR REFERENCE ONLY

|                     | S1                   | S2                   |
|---------------------|----------------------|----------------------|
| TYPE                | PLANO                | PLANO                |
| CLEAR APERTURE (mm) | 34.34 x 24.28        | N/A                  |
| SURFACE QUALITY     | 60-40                | N/A                  |
| SURFACE FLATNESS    | λ/8                  | N/A                  |
| BEVEL               | PROTECTIVE AS NEEDED | PROTECTIVE AS NEEDED |

 THIRD ANGLE  
 PROJECTION



ALL DIMS IN

mm



TITLE

26.97mm, MINOR AXIS UV ENHANCED  
 ALUMINUM ELLIPTICAL MIRROR

DWG NO

43575

SHEET  
 1 OF 1