
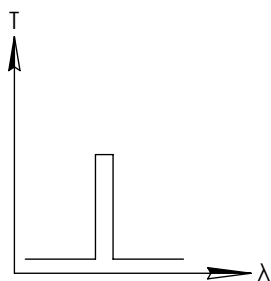
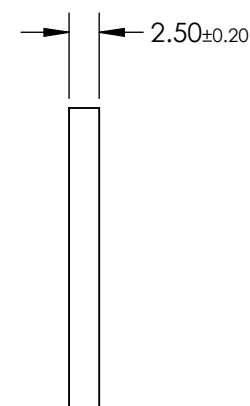
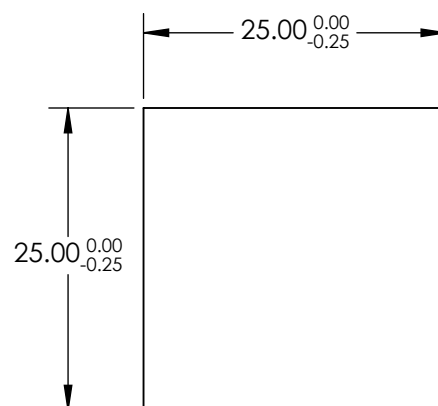


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

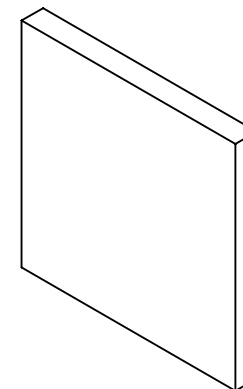

BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	410
FULL WIDTH HALF MAX (FWHM) (nm)	232
SURFACE QUALITY	80-50
CAOTING TYPE	Uncoated
BEVEL	PROTECTIVE AS NEEDED



ALL DIMS IN

mm

TITLE

HOYA B-410 (UV-VIS) 25mm Square, Colored
Glass Bandpass Filter

DWG NO

34432

SHEET
1 OF 1