
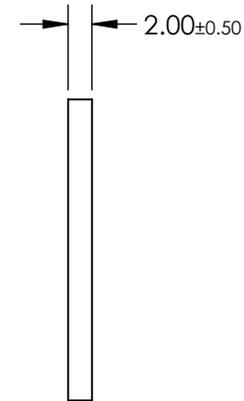
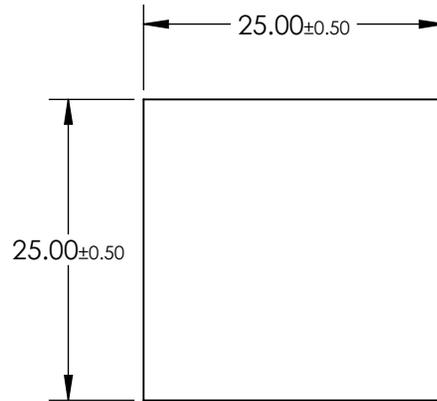
 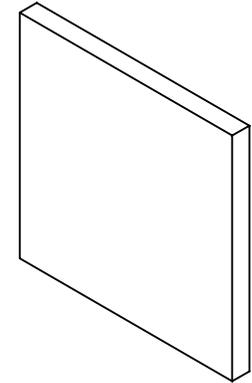


**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**



SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

SUBSTRATE	Fused Silica
GROOVE DENSITY (grooves/mm)	1200
WAVELENGTH RANGE (nm)	250 - 450
BLAZE ANGLE	26.7°
RoHS	COMPLIANT

THIRD ANGLE PROJECTION 

ALL DIMS IN mm

**EO<sup>®</sup> Edmund Optics<sup>®</sup>**

TITLE	1200 Grooves/mm, 25mm Sq, UV Transmission Grating Beamsplitter		
DWG NO	85295	SHEET	1 OF 1