
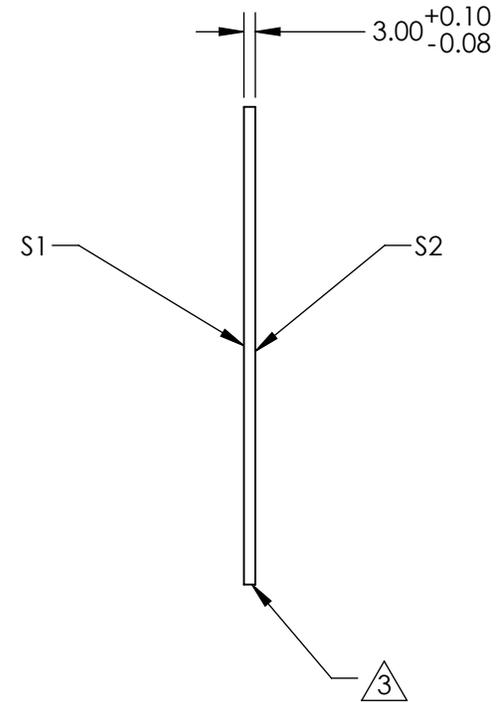
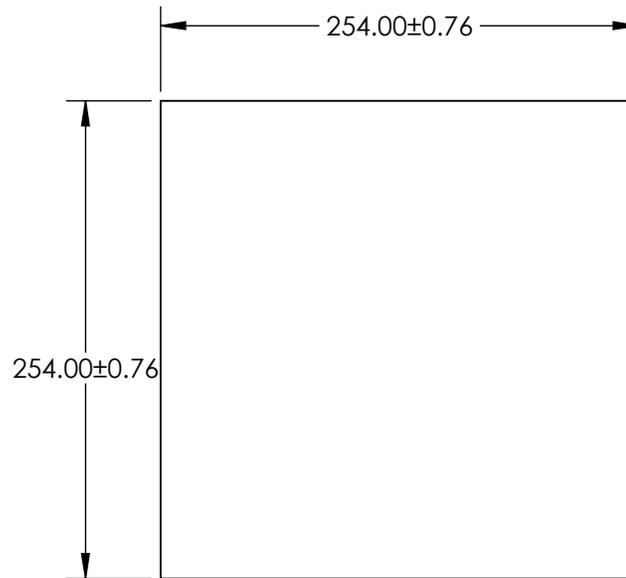


NOTES:

1. SUBSTRATE:
Float Glass
2. ANTI REFLECTION SURFACE TREATMENT (APPLY ACROSS CLEAR APERTURE)
AOI: 0°
S1 & S2: Ravg ≤0.5% @ 425 - 700nm

3. SEAMED EDGES

4. ROHS COMPLIANT

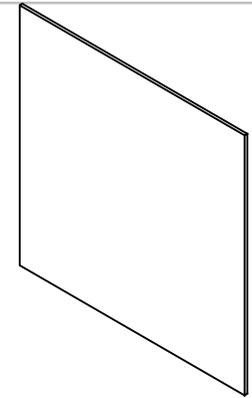

**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

| | S1 | S2 |
|-----------------|---------------------|---------------------|
| SHAPE | PLANO | PLANO |
| SURFACE QUALITY | 80-50 | 80-50 |
| CLEAR APERTURE | ≥90% | ≥90% |
| BEVEL | PROTECTED AS NEEDED | PROTECTED AS NEEDED |

THIRD ANGLE PROJECTION

ALL DIMS IN mm

EO® Edmund Optics®

TITLE

254 x 254 x 3mm High Efficiency Window

DWG NO

21331

SHEET
3 OF 4