




IM Foldable Stand

Stands for Imaging Modules

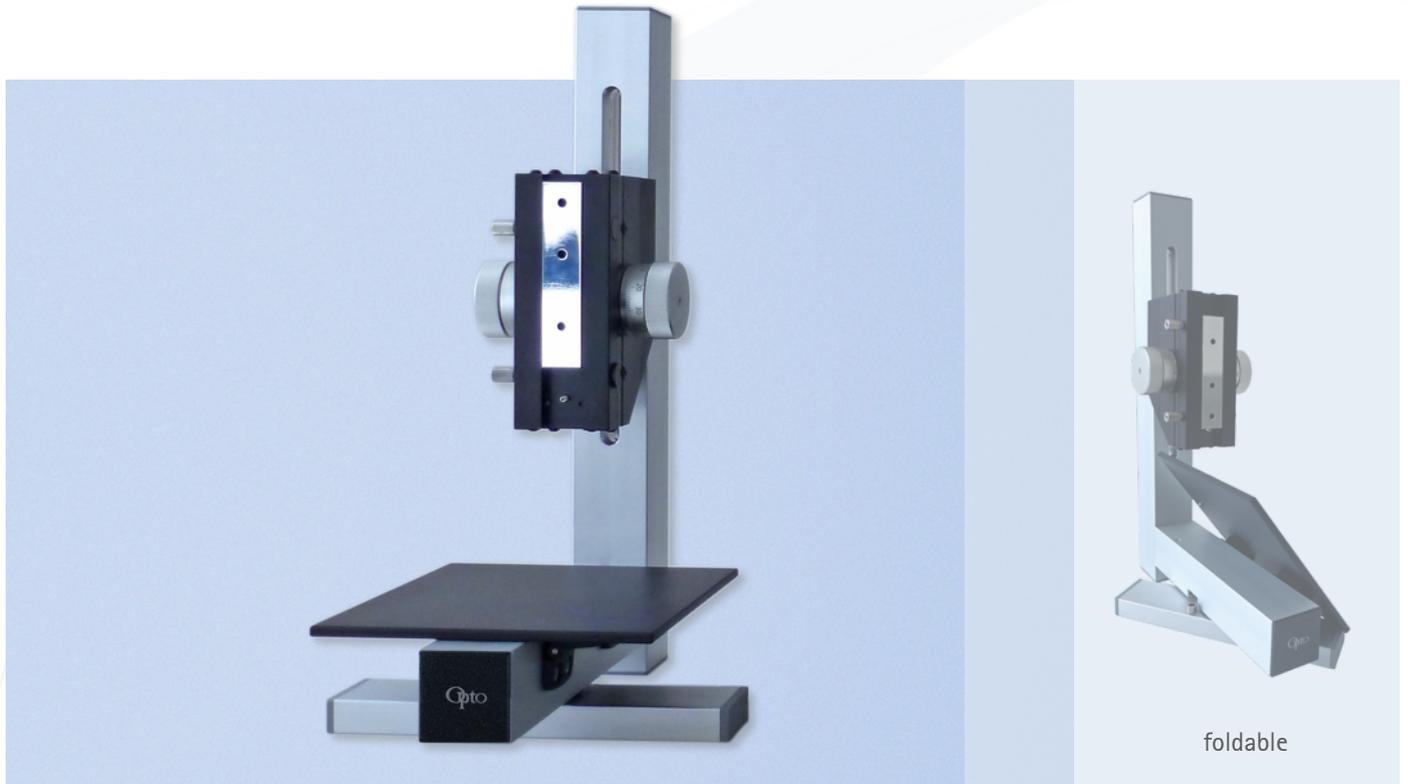

Technical Features

Article number	043-600505-350	043-600505-500
IM Foldable Stand	focus drive OC	focus drive OC
Mechanism	foldable	foldable
Size	190x230x350 mm	190x230x500 mm
Object level over ground	64 mm	64 mm
High adjustment	180 mm	330 mm
Focus travel range [mm]	70 rough / 0,24 fine	70 rough / 0,24 fine
Maximum load	15 kg	15 kg
Plate size	150x150 mm	150x150 mm
Height of folded stand	99 mm	129 mm
Fixation	Dove tail OC	Dove tail OC
Material Weight	Aluminium 2.94 kg	Aluminium 3.44 kg



Description

The IM•foldable stand is specially designed for the Imaging Modules.

As a classic - stationary - stand it takes up little space and is best suited for individual workstations.

But these stands are also foldable, for workstations that need to be flexible.



Technical Drawing

Example: 043-600505-350

